


Date : 11 Nov 19  
Version : V1


# 3-Phase 400V 32A switched + outlet measurement PDU drawing & specification

RP3000: Outlet Measurement, Outlet Switch ON / OFF, SNMP Hardware

RackPower

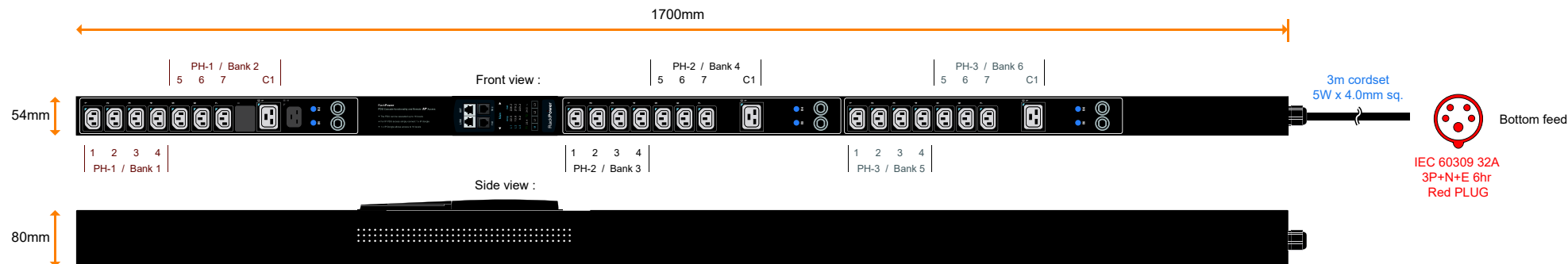

Item Number  
60110-460

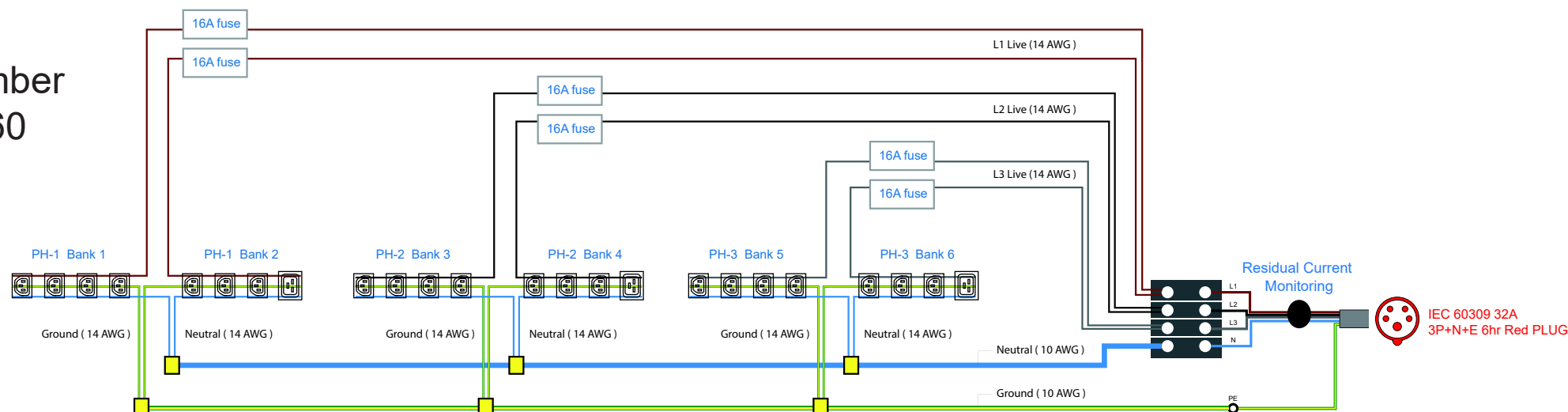

## Three phase switched PDU + outlet measurement

Input Rating : 32A, 400V 3PH  
Outlet : 10A Rated C13 x 21  
16A Rated C19 x 3  
Inlet : 32A IEC60309 3P+N+E 6hr Red plug  
Cordset : 5-wire 3 meter 4.0mm sq H07RN-F cordset  
Protection : 16A resettable fuse x 6  
Bank Details : **PH-1** < **Bank 1** > Output 16A max. C 13 #1-4  
< **Bank 2** > Output 16A max. C 13 #5-7 + C 19 #C 1  
**PH-2** < **Bank 3** > Output 16A max. C 13 #1-4  
< **Bank 4** > Output 16A max. C 13 #5-7 + C 19 #C 1  
**PH-3** < **Bank 5** > Output 16A max. C 13 #1-4  
< **Bank 6** > Output 16A max. C 13 #5-7 + C 19 #C 1

## Meter Features ( WSi Switched PDU + Outlet Measurement )

Local Display : Field replaceable 2.8" color LCD with touchscreen  
Bank Measurement : Current ( A ), Energy ( kWh ), Voltage ( V ) & Power factor  
Outlet Measurement : Current ( A ), Energy ( kWh )  
Outlet Control : Outlet Switch ON / OFF  
Accuracy :  $\pm 1\%$  Billing-grade  
IP Access : via IP dongle, one IP Access up to 16 PDU Levels  
Cascade : Up to 16 PDU under single IP address via IP dongle  
SNMP : V2 / V3 via IP dongle  
Sensor Port x 2 : Temp. Sensor / Temp. + Humid. Sensor

## Residual Current Monitoring

Measuring Range : 0 to 300 mA ( RMS )  
Measurement Accuracy : 0 to 15%  
Rated Frequency : 50 / 60 Hz  
Response Time : < 10 sec

|                        |   |                             |
|------------------------|---|-----------------------------|
| EMC Compliance         | : | CE / EMC certified          |
| Safety Compliance      | : | CE / LVD certified          |
| Environment Compliance | : | RoHS2 & REACH               |
| Operating Temperature  | : | -5 to 60 °C                 |
| Storage Temperature    | : | -25 to 65 °C                |
| Operating Altitude     | : | 0 to 2,000 m                |
| Storage Altitude       | : | 0 to 15,000 m               |
| Humidity               | : | 8 to 95% RH, non-condensing |

|                   |   |                               |
|-------------------|---|-------------------------------|
| Chassis Material  | : | Steel                         |
| Chassis Color     | : | Black                         |
| Product Dimension | : | 54 (W) x 80 (D) x 1700 (H) mm |
| Net Weight        | : | 8 kg                          |

|                                  |   |                                 |
|----------------------------------|---|---------------------------------|
| Packing Dimension ( for 2 PDUs ) | : | 110 (W) x 268 (D) x 2043 (H) mm |
| PDU Gross Weight ( for 2 PDUs )  | : | 18 kg                           |