
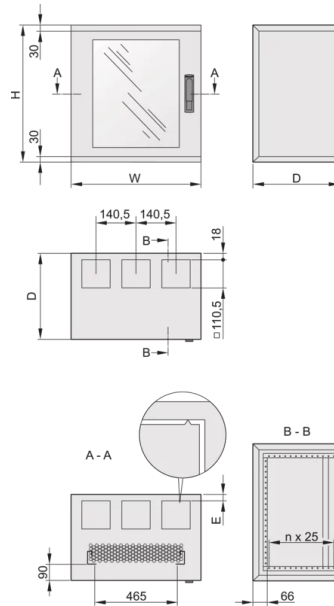


## 10236-161 EPCASE 19" WALL MOUNT CABINET, 16 U, 500 DEPTHS

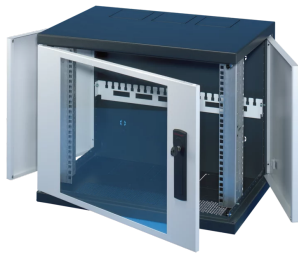

### KEY FEATURES

Cable support rail is included and is adjustable in 25 mm increments

Type of protection IP 20

Multi function 19" wall case with hinged side panels

19" panel/slide mounts are depth-adjustable in 25 mm increments

Cable entry from above or below; the cable entry opening can be sealed with two brush strips each, or can be used to assemble fan

### PRODUCT ATTRIBUTES

Product Type: Case

Product Family: Epcase

Rack Height: 16 U

Height: 812 mm

Width: 600 mm

Depth: 500 mm

Weight: 30 kg

Finish: Powder Coated

Material: Steel

Static Load: 30 kg

Protection Rating: IP20; NEMA Type 1

## ADDITIONAL PRODUCT DETAILS

---

Multi function 19" wall case with hinged side panels.

## CERTIFICATIONS

---



### North America

All locations

+1.763.422.2661

Chat with us:

[schroff.nvent.com](https://schroff.nvent.com)

### Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[schroff.nvent.com](https://schroff.nvent.com)

### Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[schroff.nvent.com](https://schroff.nvent.com)

### Middle East & India

Dubai, United Arab Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[schroff.nvent.com](https://schroff.nvent.com)



Our powerful portfolio of brands:  
[nVent.com](https://nVent.com) **CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER**

© 2024 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.