


## 10238-151 EPCASE 10" WALL MOUNT CABINET, 4 U, 280 DEPTHS

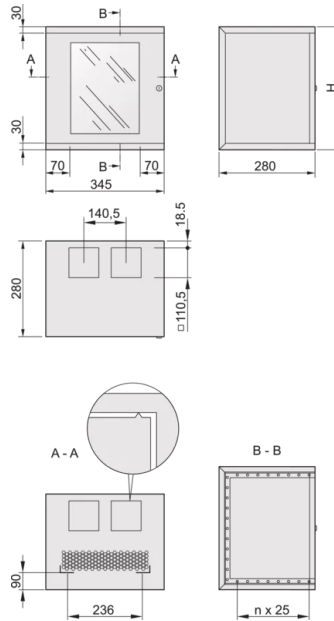

### KEY FEATURES

10" slide mounts are depth-adjustable in 25 mm increments

Completely pre-assembled

Cable entry from above or below; the cable entry opening can be sealed with a brush strip

### PRODUCT ATTRIBUTES

Product Type: Case

Product Family: Epcase

Type: Wall Mount

Rack Height: 4 U

Height: 262 mm

Width: 345 mm

Depth: 280 mm

Weight: 5 kg

EMC Shielding: No

Finish: Powder Coated

Material: Steel

Static Load: 25 kg

Protection Rating: IP20

## ADDITIONAL PRODUCT DETAILS

---

Multi function 10" wall case with hinged side panels.

Lever handle and DIN profile half cylinder cannot be retrofitted.

## CERTIFICATIONS

---



### North America

All locations

+1.763.422.2661

Chat with us:

[schroff.nvent.com](https://schroff.nvent.com)

### Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[schroff.nvent.com](https://schroff.nvent.com)

### Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[schroff.nvent.com](https://schroff.nvent.com)

### Middle East & India

Dubai, United Arab Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[schroff.nvent.com](https://schroff.nvent.com)



Our powerful portfolio of brands:  
[nVent.com](https://nVent.com) **CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER**

© 2024 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.