
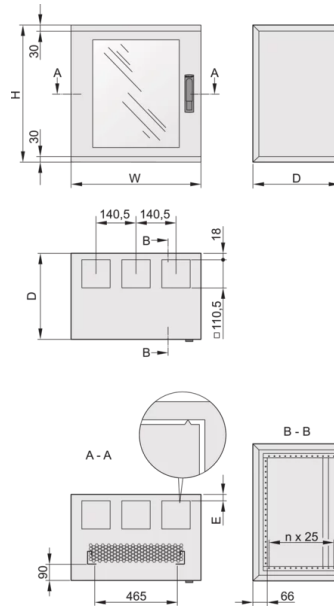


10236-156 EPCASE 19" WALL MOUNT CABINET, 12 U, 400 DEPTHS

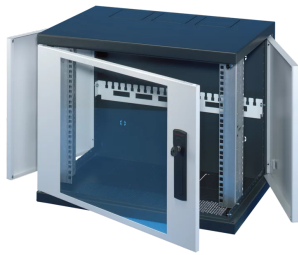

KEY FEATURES

Cable support rail is included and is adjustable in 25 mm increments

Type of protection IP 20

Multi function 19" wall case with hinged side panels

19" panel/slide mounts are depth-adjustable in 25 mm increments

Cable entry from above or below; the cable entry opening can be sealed with two brush strips each, or can be used to assemble fan

PRODUCT ATTRIBUTES

Product Type: Case

Product Family: Epcase

Rack Height: 12 U

Height: 612 mm

Width: 600 mm

Depth: 400 mm

Weight: 24 kg

Finish: Powder Coated

Material: Steel

Static Load: 35 kg

Protection Rating: IP20; NEMA Type 1

ADDITIONAL PRODUCT DETAILS

Multi function 19" wall case with hinged side panels.

CERTIFICATIONS



North America

All locations
+1.763.422.2661
Chat with us:
schroff.nvent.com

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
schroff.nvent.com

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
schroff.nvent.com

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
schroff.nvent.com



Our powerful portfolio of brands:
nVent.com **CADDY ERICO HOFFMAN RAYCHEM SCHROFF TRACER**

© 2024 nVent. All nVent marks and logos are owned or licensed by nVent Services GmbH or its affiliates. All other trademarks are the property of their respective owners.

nVent reserves the right to change specifications without notice.