


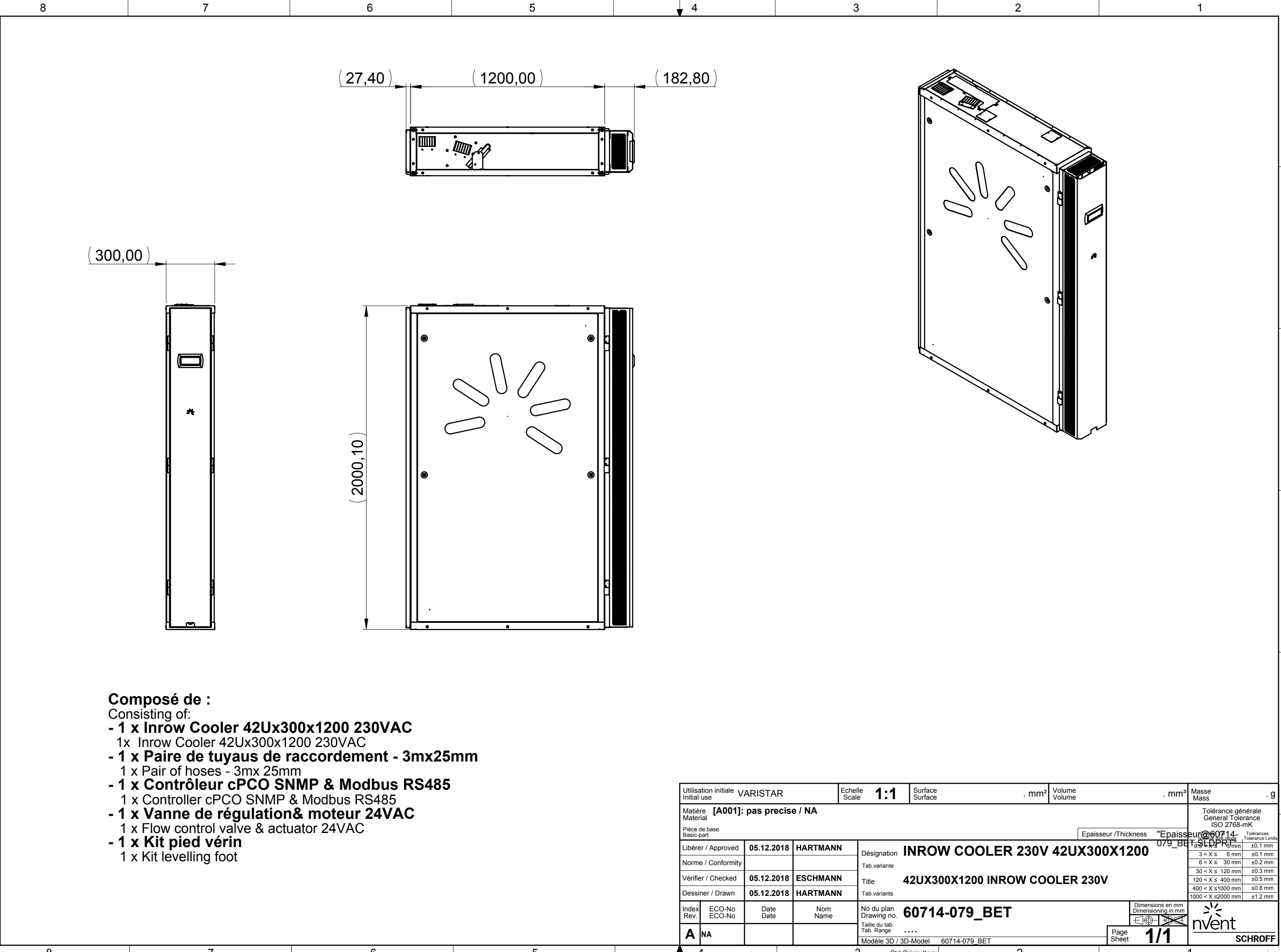

- Composé de :**
Consisting of:
- **1 x Inrow Cooler 42Ux300x1200 230VAC**
1x Inrow Cooler 42Ux300x1200 230VAC
 - **1 x Paire de tuyaus de raccordement - 3mx25mm**
1 x Pair of hoses - 3mx 25mm
 - **1 x Contrôleur cPCO SNMP & Modbus RS485**
1 x Controller cPCO SNMP & Modbus RS485
 - **1 x Vanne de régulation& moteur 24VAC**
1 x Flow control valve & actuator 24VAC
 - **1 x Kit pied vérin**
1 x Kit levelling foot

Utilisation initiale Initial use				VARISTAR		Echelle Scale	1:1		Surface Surface	. mm²	Volume Volume	. mm³	Masse Mass	. g
Matière Material												Tolérance générale General Tolerance ISO 2768-mK		
Pièce de base Basic-part												Tolérances Tolerance Limits		
Libérer / Approved		05.12.2018		HARTMANN		Désignation		INROW COOLER 230V 42UX300X1200						
Norme / Conformity						Tab.variante								
Vérifier / Checked		05.12.2018		ESCHMANN		Title		42UX300X1200 INROW COOLER 230V						
Dessiner / Drawn		05.12.2018		HARTMANN		Tab.variants								
Index Rev.		ECO-No ECO-No		Date Date		Nom Name		No du plan Drawing no.		60714-079_BET				
A		NA						Taille du tab. Tab. Range						
								Modèle 3D / 3D-Model		60714-079_BET				