 
 




Front view :



Rear view :



Top View :

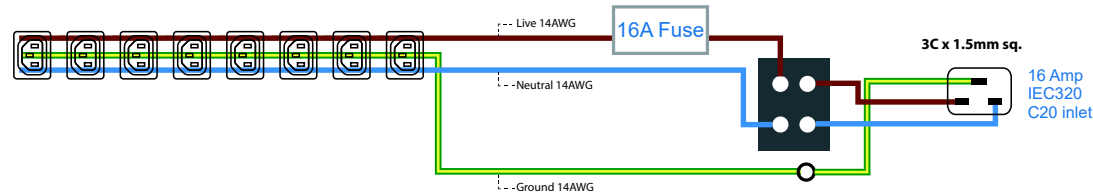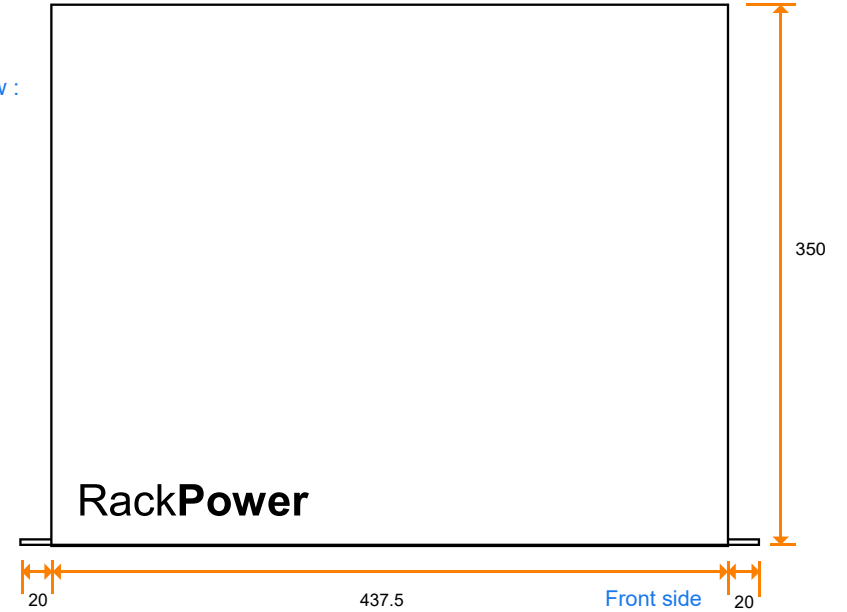

Item Number
60110-461

unit : mm

Single phase switched + outlet measurement PDU

- Input Rating : 16A, 230V
- Outlet : 10A Rated C13 x 8
- Inlet : 16A IEC320 C20 inlet
- Cordset : NIL
- Protection : 16A resettable fuse x 1
- Circuit Details : Output 16A max. C 13 # 1 - 8

Meter Features (WSi Switched PDU + Outlet Measurement)

- Local Display : Field replaceable 2.0" color LCD with touchscreen
- Bank Measurement : Current (A), Energy (kWh), Voltage (V) & Power factor
- Outlet Measurement : Current (A), Energy (kWh)
- Outlet Control : Outlet Switch ON / OFF
- Accuracy : ±1% Billing-grade
- IP Access : via IP dongle, one IP Access up to 16 PDU Levels
- Cascade : Up to 16 PDU under single IP address via IP dongle
- SNMP : V2 / V3 via IP dongle
- Sensor Port x 2 : Temp. Sensor / Temp. + Humid. Sensor

- EMC Compliance : FCC & CE certified
- Safety Compliance : CE / LVD certified
- Environment Compliance : RoHS2 & REACH

- Operating Temperature : -5 to 60 °C
- Storage Temperature : -25 to 65 °C
- Operating Altitude : 0 to 2,000 m
- Storage Altitude : 0 to 15,000 m
- Humidity : 8 to 95% RH, non-condensing

- Chassis Material : Steel
- Chassis Color : Black

- Product Dimension : 437.5 (W) x 350 (D) x 44.5 (H) mm
- Net Weight : 4.56 kg

- Packing dimension : 550 (W) x 550 (D) x 160 (H) mm
- PDU gross weight : 4.82 kg