

# Varistar CP Server And Networking Cabinet



## CONNECT AND PROTECT YOUR IT ASSETS



The more complex and demanding the conditions of your IT infrastructure, the more you ask from a server or networking cabinet.

With its outstanding characteristics, the nVent SCHROFF Varistar CP series connect and protect you IT assets. Satisfy even the most complex requirements on loading capacity, cable management and security.

### FEATURES

- 1,600 kg static load
- 1,000 kg dynamic load with integrated castors
- Prepared for secure access control options
- Unique meander type profile for maximum fixing flexibility
- One tool required as all screws TORX 30
- Pre-configured cabinets with short lead time and starting point for individual configurations and modifications

### PRE-CONFIGURED VARISTAR CP CABINETS

- Perforated (80%) single front and double door at the rear
- 19" uprights mounted in 740 mm distance reconfigurable in 25 mm steps including RU marking
- Top cover with cut-outs and brushes, optimized for maximum cable entry space
- Side panels with quick releases
- Grounding kit
- Cabinet surface fully electrostatically powder-coated in RAL 7021 (anthracite)

Catalog Number	Usable RU	Height [mm]	Width [mm]	Depth [mm]	Integrated Castors
10630001	42	2000	600	1200	
10630002	47	2200	600	1200	
10630003	42	2000	800	1200	
10630004	47	2200	800	1200	
10630005	42	2000	600	1200	Yes
10630006	47	2200	600	1200	Yes
10630007	42	2000	800	1200	Yes
10630008	47	2200	800	1200	Yes
10630009	42	2000	600	1000	
10630010	47	2200	600	1000	
10630011	42	2000	800	1000	
10630012	47	2200	800	1000	
10630013	42	2000	600	1000	Yes
10630014	47	2200	600	1000	Yes
10630015	42	2000	800	1000	Yes
10630016	47	2200	800	1000	Yes


# Varistar CP Server And Networking Cabinet



## STABILITY

Tested static loading capacity of 1,600 kg

- Integrated castor design
- Depth-adjustable 19" plane
- Static loading capacity of 1,600 kg
- Dynamic loading capacity of 1,000 kg

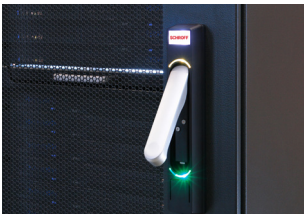

## LOCKING SYSTEM

Mechanical design in combination with locking system ensures access security to 100 %

- Various locking options also HID and Mifare electronic locks



## STRUCTURED CABLE MANAGEMENT

Avoid air resistance, strains, bends and pressure points to ensure performance

- Optimized cable entry points with maximum space
- Full range of cable management accessories



## LEADING DESIGN

One tool required for all screws

- One person assembly due to sophisticated side panel design
- Recessable 19" angles
- Pre-configured standard dimensions

## EUROPE

**Straubenhardt, Germany**

Tel +49.7082.794.0

**Betschdorf, France**

Tel +33.388.90.64.90

**Warsaw, Poland**

Tel +48.22.209.98.35

**Lainate, Italy**

Tel +39.02.5776151.224

## NORTH AMERICA

**All locations**

Tel: +1.763.422.2661

## MIDDLE EAST & INDIA

**Dubai, United Arabian Emirates**

Tel: +971.4.37.81.700

**Bangalore, India**

Tel: +91.80.6715.2001

**Istanbul, Turkey**

Tel: +90.216.250.7374

## ASIA

**Shanghai, China**

Tel +86.21.2412.6943

**Qingdao, China**

Tel +86.523.8771.6101

**Singapore**

Tel +65.6768.5800

**Shin-Yokohama, Japan**

Tel +81.45.476.0271



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

RAYCHEM

SCHROFF

TRACER